

SCOUT

814SUFC200P60 180° smart

EAN 4031582429916

Swivel castor, stainless steel housing and automatic directional stability, precision ball bearing in swivel bearing with long-term grease, swivel bearing with dust protection and grease nipple, plate fitting, prepared for optional directional lock. Swivel castor with automatic directional stability, plate fitting. Wheel centre made of polyamide, tread made of a non-marking elastic tyre, with small thread guard, two INOX precision ball bearings, sealed, washable



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

| | |
|---------------------|--------------|
| Wheel diameter | 200 mm |
| Wheel width | 40 mm |
| Castor width | 72 mm |
| Size of Plate | 130 x 74 mm |
| Plate hole centres | 110 x 50 mm |
| Plate hole | 10,5 mm |
| Offset | 50 mm |
| Swivel Interference | 300 mm |
| Overall height | 242 mm |
| Temperature | -20 / +80 °C |
| Weight | 2.912 kg |
| Swivel Radius | 150 mm |
| Hardness of tread | Shore A 64 |
| Load capacity | 150 kg |

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ○ ○ |
| Movement noise | ● ● ● ● ● |
| Attrition | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ○ ○ |

Structure & Mounting

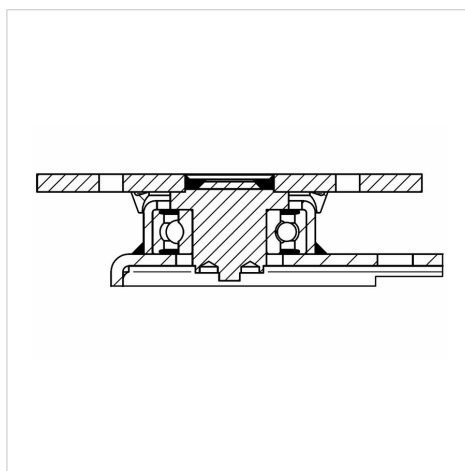

SCOUT

814SUFC200P60 180° smart

EAN 4031582429916



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

