

MONO

A025PJI050L51-10 RAL7035

EAN 4031582359886

Swivel castor with wheel brake, housing made of Polypropylene, with blind hole fitting. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

Wheel diameter	50 mm
Wheel width	18 mm
Centre hole	10 mm
Offset	25 mm
Swivel Interference	143.6 mm
Overall height	72 mm
Temperature	- 20 / + 60 °C
Standard	EN_12528
Weight	0.78 kg
Swivel Radius	71.8 mm
Hardness of tread	Shore A 85
Load capacity	30 kg
Load capacity (static)	60 kg

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ○

Dimensions

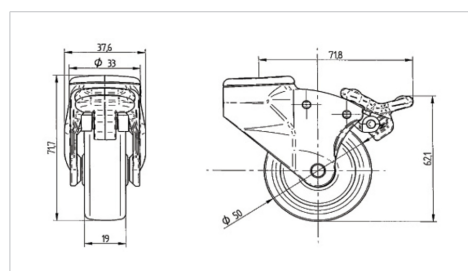

Structure & Mounting

