

# NOVATECH

## ETP080x25-Ø20 HL14

EAN 4031582318531

Wheel centre made of steel, Tread: Polyurethane, casted, precision ball bearing.

Load capacities on a smooth, even surface.



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

|                        |                |
|------------------------|----------------|
| Wheel diameter         | 80 mm          |
| Wheel width            | 25 mm          |
| Axle Hole-Ø            | 20 mm          |
| Hub length             | 14 mm          |
| Temperature            | - 10 / + 60 °C |
| Standard               | EN_12532       |
| Weight                 | 0.38 kg        |
| Hardness of tread      | Shore A 92     |
| Load capacity          | 160 kg         |
| Load capacity (static) | 320 kg         |

### Dimensions

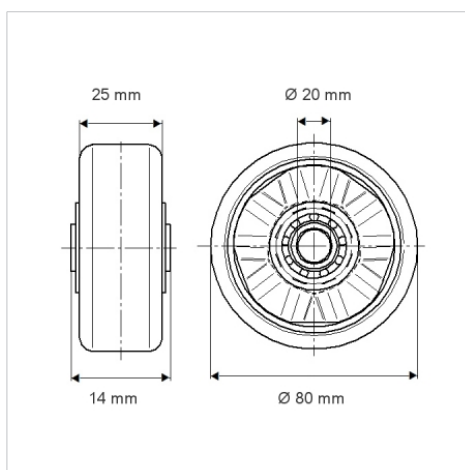

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ● ○ |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ○ ○ |

### Structure & Mounting

