

# NOVATECH

## STP500x80-Ø50 HL90

EAN 4031582322293

Wheel centre made of pressed steel, lacquered, heavy duty, Tread: Polyurethane, casted, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

|                        |                |
|------------------------|----------------|
| Wheel diameter         | 500 mm         |
| Wheel width            | 80 mm          |
| Axle Hole-Ø            | 50 mm          |
| Hub length             | 90 mm          |
| Temperature            | - 10 / + 60 °C |
| Standard               | EN_12533       |
| Weight                 | 40.634 kg      |
| Hardness of tread      | Shore A 92     |
| Load capacity          | 3200 kg        |
| Load capacity (static) | 6400 kg        |

### Dimensions

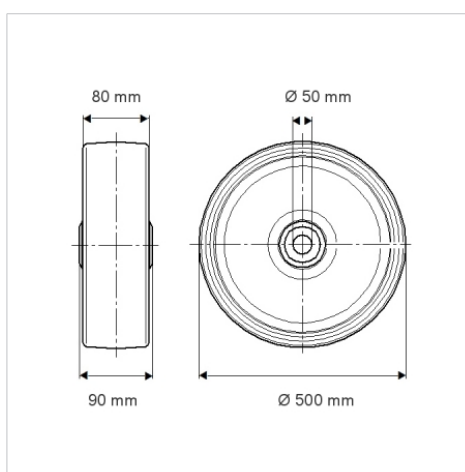

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ○ ○ |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ○ ○ |

### Structure & Mounting

