

FORMA

6945UFP125P33 grey

EAN 4031582477368

Swivel castor with wheel brake, housing made of alu die-casting, powder coated, plate fitting. Wheel centre made of Polyamide, Tread: elastic-tyre, non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

| | |
|--------------------|-----------------|
| Wheel diameter | 125 mm |
| Wheel width | 18 mm |
| Size of Plate | 92 x 64 mm |
| Plate hole centres | 73 x 45/43 mm |
| Plate hole | 10.7 x 9.5 mm |
| Offset | 41 mm |
| Overall height | 166 mm |
| Temperature | - 18 / + 120 °C |
| Swivel Radius | 117 mm |
| Hardness of tread | Shore 60 A |
| Load capacity | 125 kg |

Structure & Mounting

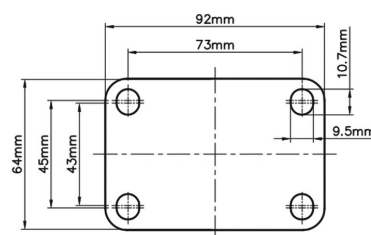

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ● ○ |
| Movement noise | ● ● ● ● ○ |
| Attrition | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ○ ○ |