

LEVINA LIGHT

5220PJP075B10-11x20

EAN 4031582492385

Swivel castor, Housing made of glass-filled Polyamide, stem with circlip.
Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

| | |
|-------------------------|----------------|
| Wheel diameter | 75 mm |
| Wheel width | 25 mm |
| Metal stem with circlip | 11x20 mm |
| Offset | 27 mm |
| Swivel Interference | 129 mm |
| Overall height | 108 mm |
| Temperature | - 10 / + 40 °C |
| Standard | EN_12530 |
| Weight | 0.2 kg |
| Swivel Radius | 64.5 mm |
| Hardness of tread | Shore A 87 |
| Load capacity | 75 kg |

Dimensions

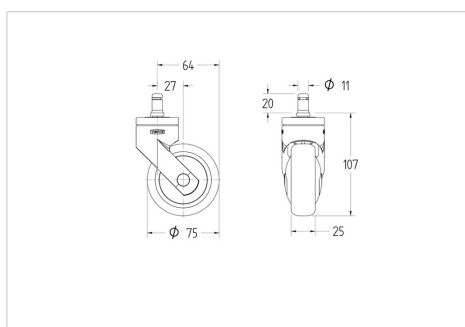

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ○ ○ |
| Movement noise | ● ● ● ● ○ |
| Attrition | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ● ○ |