

# LEVINA LIGHT

## 5220PJP075P52

EAN 4031582492538

Swivel castor, Housing made of glass-filled Polyamide, plate fitting. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	75 mm
Wheel width	25 mm
Size of Plate	95x70 mm
Plate hole centres	52/44.5x76/72 mm
Plate hole	11 mm
Offset	27 mm
Swivel Interference	129 mm
Overall height	116 mm
Temperature	- 10 / + 40 °C
Standard	EN_12530
Weight	0.384 kg
Swivel Radius	64.5 mm
Hardness of tread	Shore A 87
Load capacity	75 kg

### Dimensions

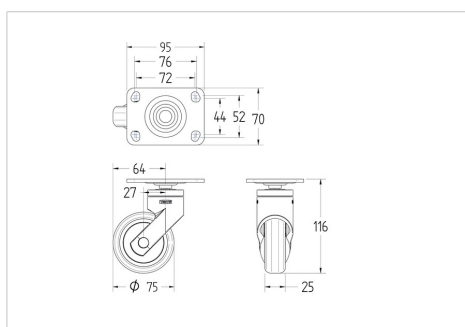

### Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ○