

LEVINA LIGHT

5220PJP125B10-11x31

EAN 4031582493009

Swivel castor, Housing made of glass-filled Polyamide, stem with circlip.
Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	125 mm
Wheel width	32 mm
Metal stem with circlip	11x31 mm
Offset	38 mm
Swivel Interference	201 mm
Overall height	165 mm
Temperature	- 10 / + 40 °C
Standard	EN_12530
Weight	0.484 kg
Swivel Radius	100.5 mm
Hardness of tread	Shore A 87
Load capacity	82 kg

Dimensions

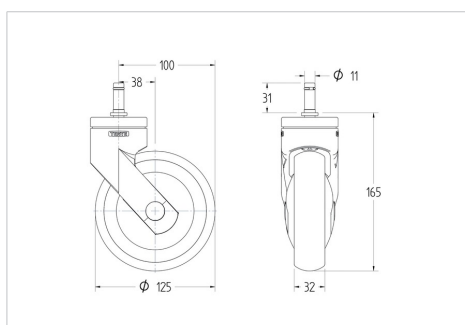

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ○

LEVINA LIGHT

5220PJP125B10-11x31

EAN 4031582493009



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

