

# AGILA

## 2478XSP100P50

EAN 4031582344851

Fixed castor, Fork made of pressed steel, bright zinc plated, blue passivated, wheel axle with nut, plate fitting.

Longside of plate 90° off track.

Wheel centre made of Polyamide, electric conductive, tread made of Polyurethane, with threadguards, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

|                        |                        |
|------------------------|------------------------|
| Wheel diameter         | 100 mm                 |
| Wheel width            | 32 mm                  |
| Castor width           | 60 mm                  |
| Size of Plate          | 77 x 67 mm             |
| Plate hole centres     | 61,5/56 x 51,5/46,5 mm |
| Plate hole             | 8,5 mm                 |
| Dome-Ø                 | 60 mm                  |
| Overall height         | 135 mm                 |
| Temperature            | - 20 / + 60 °C         |
| Standard               | EN_12530               |
| Weight                 | 0.581 kg               |
| Hardness of tread      | Shore D 40             |
| Load capacity          | 100 kg                 |
| Load capacity (static) | 200 kg                 |

### Dimensions

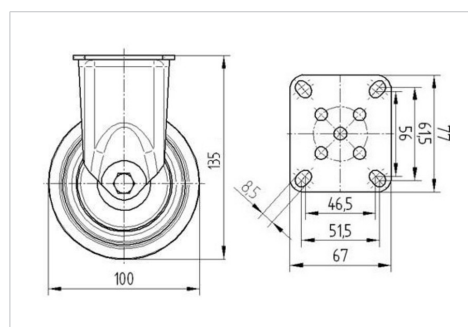

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ○ ○ |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ○ ○ |

# AGILA

2478XSP100P50

EAN 4031582344851



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

