

AGILA

7470XSC125P50

EAN 4031582349863

Swivel castor, housing made of Stainless Steel, double ball bearing swivel head, wheel axle with nut, plate fitting. Wheel centre made of Polyamide, electric conductive, tread made of Polyurethane, with threadguards, precision ball bearing, stainless

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

Wheel diameter	125 mm
Wheel width	32 mm
Castor width	60 mm
Size of Plate	77 x 67 mm
Plate hole centres	61,5/56 x 51,5/46,5 mm
Plate hole	8,5 mm
Dome-Ø	60 mm
Offset	41 mm
Swivel Interference	207 mm
Overall height	160 mm
Temperature	- 25 / + 80 °C
Standard	EN_12530
Weight	0.794 kg
Swivel Radius	103.5 mm
Hardness of tread	Shore A 91
Load capacity	100 kg
Load capacity (static)	200 kg


Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ●

Dimensions

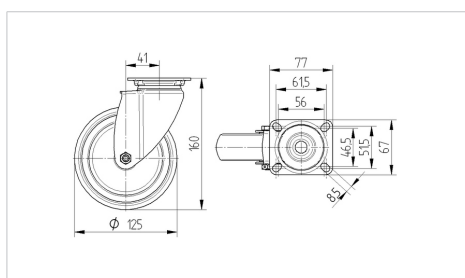

Structure & Mounting

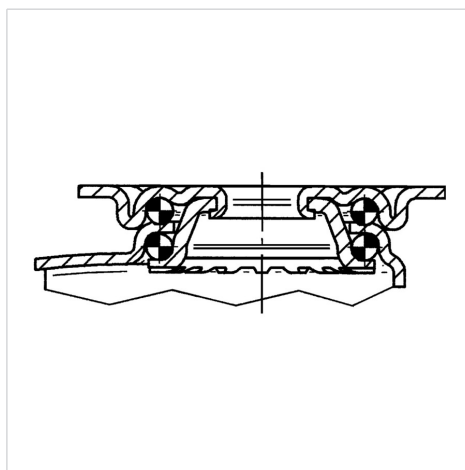

AGILA

7470XSC125P50

EAN 4031582349863



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

