

# PURETECH

DIK075x25-Ø6

EAN 4031582070149

Wheel centre made of pressed steel, Tread: solid rubber, grey non-marking, with threadguards, cone ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

Wheel diameter	75 mm
Wheel width	25 mm
Axle Hole-Ø	6 mm
Hub length	28 mm
Temperature	- 20 / + 85 °C
Standard	EN_12530
Weight	0.22 kg
Hardness of tread	Shore A 80
Load capacity	55 kg
Load capacity (static)	110 kg

## Dimensions

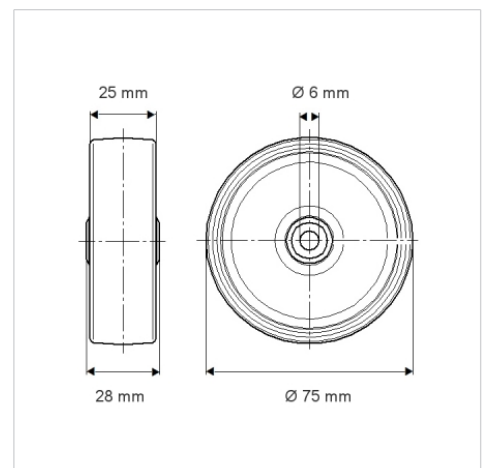

## Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○