

# BASETECH

## POR125x40-Ø12 HL48

EAN 4031582320817

Wheel centre made Polypropylene, roller bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	125 mm
Wheel width	40 mm
Axle Hole-Ø	12 mm
Hub length	48 mm
Temperature	- 20 / + 60 °C
Standard	EN_12532
Weight	0.207 kg
Hardness of tread	Shore D 65
Load capacity	200 kg
Load capacity (static)	400 kg

### Dimensions

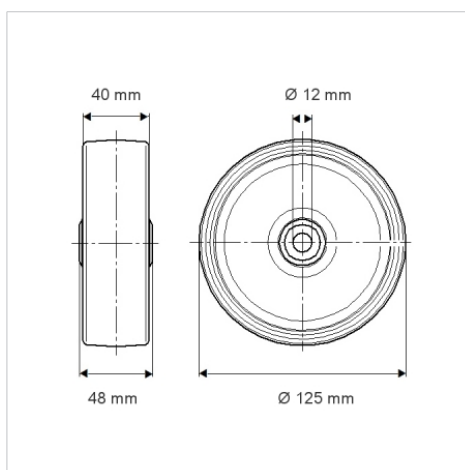

### Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ○ ○