

LINEA**5941UAC100P30-13 RAL9002**

EAN 4031582352603

Swivel castor with directional lock, housing made of Polyamide, precision ball bearing in swivel head, bolt hole. Wheel centre made of polyamide, tread made of polyurethane, two INOX precision ball bearings, sealed, washable

TENTE

BETTER MOBILITY. BETTER LIFE.



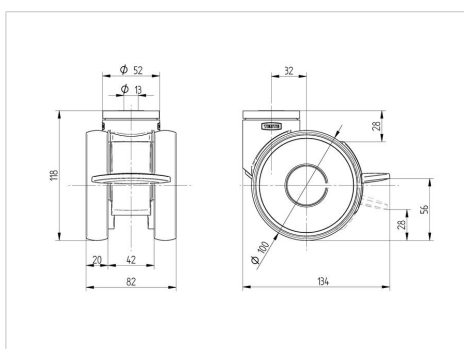
Picture may differ from original product

Technical Data

| | |
|------------------------|----------------|
| Wheel diameter | 100 mm |
| Wheel width | 20 mm |
| Castor width | 82 mm |
| Centre hole | 13 mm |
| Dome-Ø | 52 mm |
| Offset | 32 mm |
| Swivel Interference | 216 mm |
| Overall height | 118 mm |
| Temperature | - 10 / + 40 °C |
| Standard | EN_12530 |
| Weight | 0.723 kg |
| Swivel Radius | 108 mm |
| Hardness of tread | Shore A 92 |
| Load capacity | 120 kg |
| Load capacity (static) | 240 kg |

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ● ● |
| Movement noise | ● ● ● ○ ○ |
| Attrition | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ● ○ |

Dimensions**Structure & Mounting**