

# LEVINA LIGHT

5220PJP075S70-10x15

EAN 4031582492569

Swivel castor, Housing made of glass-filled Polyamide, threaded stem with hexagon neck. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


## Technical Data

|                     |                |
|---------------------|----------------|
| Wheel diameter      | 75 mm          |
| Wheel width         | 25 mm          |
| Threaded stem       | M10x15 mm      |
| Offset              | 27 mm          |
| Swivel Interference | 129 mm         |
| Overall height      | 109 mm         |
| Temperature         | - 10 / + 40 °C |
| Standard            | EN_12530       |
| Weight              | 0.194 kg       |
| Hardness of tread   | Shore A 87     |
| Load capacity       | 75 kg          |

## Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ○ ○ |
| Movement noise       | ● ● ● ● ○ |
| Attrition            | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ● ○ |

## Dimensions

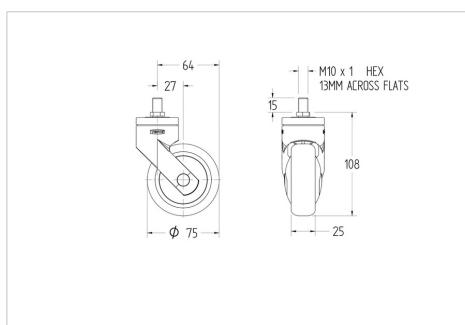

## Structure & Mounting

