

# LEVINA

## 5370PJP125P50

EAN 4031582347487

Swivel castor, housing and wheels made from high grade synthetic materials, double ball bearing swivel head, plate fitting. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product


### Technical Data

|                        |                        |
|------------------------|------------------------|
| Wheel diameter         | 125 mm                 |
| Wheel width            | 32 mm                  |
| Castor width           | 59 mm                  |
| Size of Plate          | 77 x 67 mm             |
| Plate hole centres     | 61,5/56 x 51,5/46,5 mm |
| Plate hole             | 8,5 mm                 |
| Dome-Ø                 | 59 mm                  |
| Offset                 | 38 mm                  |
| Swivel Interference    | 201 mm                 |
| Overall height         | 161 mm                 |
| Temperature            | - 10 / + 40 °C         |
| Standard               | EN_12530               |
| Weight                 | 0.574 kg               |
| Swivel Radius          | 100.5 mm               |
| Hardness of tread      | Shore A 87             |
| Load capacity          | 100 kg                 |
| Load capacity (static) | 200 kg                 |

### Dimensions

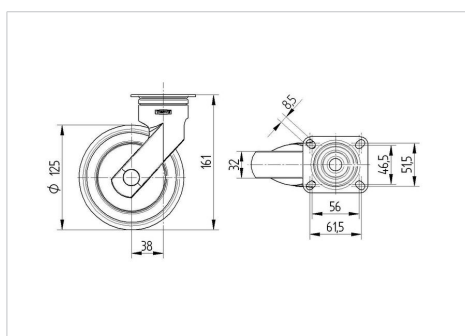

### Structure & Mounting

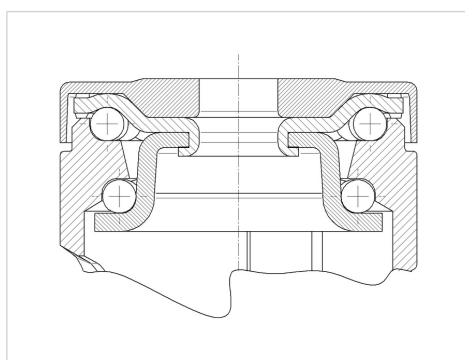

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ○ ○ |
| Movement noise       | ● ● ● ● ○ |
| Attrition            | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ● ○ |

# LEVINA


5370PJP125P50

EAN 4031582347487



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

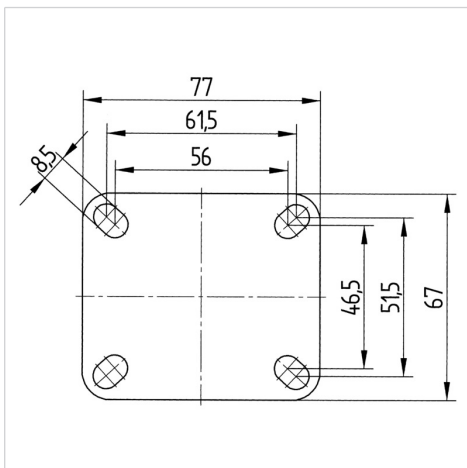

**Design Award Winner**

German Designer Club

