

FORMA

694GUF150R26-28 S45 4xM8 grey

EAN 4031582476286

Swivel castor, central lock with three positions: directional lock, wheel lock and free movement, housing made of alu die-casting, powder coated, stem with cam hole for profile bars. Wheel centre made of Polyamide, Tread: elastic-tyre, non-marking, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	150 mm
Wheel width	18 mm
Bolt-Ø	28 mm
Bolt length	97 mm
Offset	57 mm
Overall height	177 mm
Temperature	- 18 / + 120 °C
Swivel Radius	137 mm
Hardness of tread	Shore 60 A
Load capacity	135 kg

Structure & Mounting

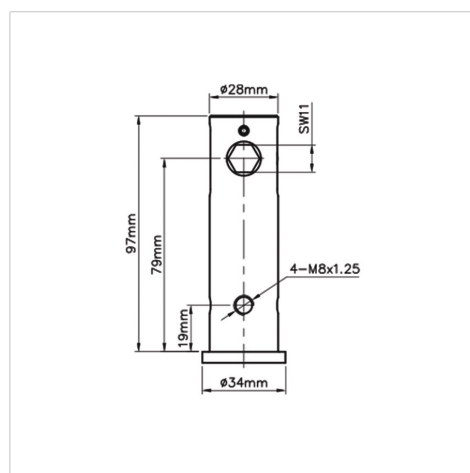

Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ○ ○