

SCOUT

8148UAC160P60 TFR

EAN 4031582481785

Fixed castor, stainless steel housing, plate fitting. Fixed castor, Housing made of stainless steel, plate fitting. Wheel centre made of polyamide, tread made of polyurethane, two INOX precision ball bearings, sealed, washable



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	160 mm
Wheel width	40 mm
Castor width	74 mm
Size of Plate	130 x 74 mm
Plate hole centres	110 x 50 mm
Plate hole	10.5 mm
Overall height	202 mm
Temperature	-40 / +80 °C
Standard	EN_12532
Weight	1.98 kg
Hardness of tread	Shore A 92
Load capacity	250 kg
Load capacity (static)	500 kg

Dimensions

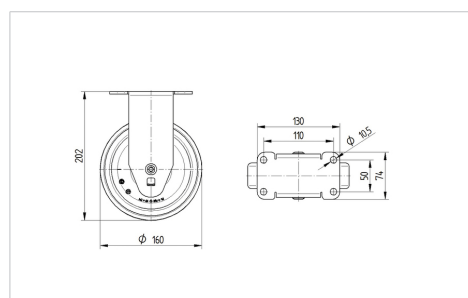

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ○ ○ ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ● ●