

# ALPHA

## 3478UOH080P62

EAN 4031582307016

Fixed castor, Fork made of pressed steel, bright zinc plated, blue passivated, wheel axle with nut, plate fitting.  
Wheel centre made of Polyamide, with threadguards, plain bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	80 mm
Wheel width	34 mm
Castor width	85 mm
Size of Plate	103 x 85 mm
Plate hole centres	80/77 x 60 mm
Plate hole	9 mm
Overall height	108 mm
Temperature	- 40 / + 80 °C
Standard	EN_12532
Weight	0.423 kg
Hardness of tread	Shore D 75
Load capacity	200 kg
Load capacity (static)	400 kg

### Dimensions

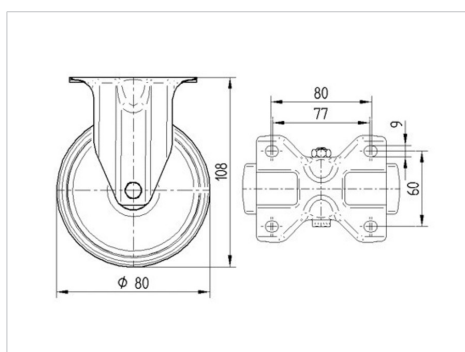

### Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ○ ○

# ALPHA

3478UOH080P62

EAN 4031582307016



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

