

# NOVATECH

## FTP250x80-Ø30 HL90

EAN 4031582319422

Wheel centre made of cast iron, Tread: Polyurethane, casted, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	250 mm
Wheel width	80 mm
Axle Hole-Ø	30 mm
Hub length	90 mm
Temperature	- 10 / + 60 °C
Standard	EN_12533
Weight	9.262 kg
Hardness of tread	Shore A 92
Load capacity	1800 kg
Load capacity (static)	3600 kg

### Dimensions

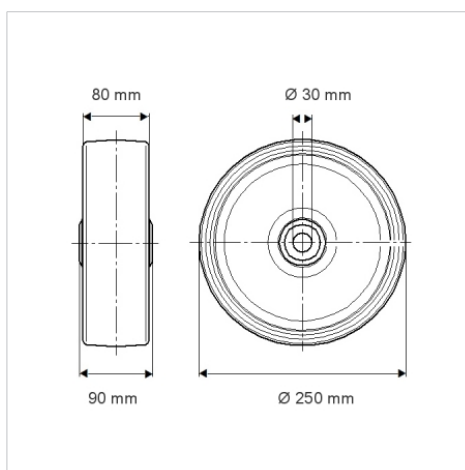

### Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ○ ○

### Structure & Mounting

