

NOVATECH

STP400x100-Ø40 HL120

EAN 4031582322262

Wheel centre made of pressed steel, lacquered, heavy duty, Tread: Polyurethane, casted, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

| | |
|------------------------|----------------|
| Wheel diameter | 400 mm |
| Wheel width | 100 mm |
| Axle Hole-Ø | 40 mm |
| Hub length | 120 mm |
| Temperature | - 10 / + 60 °C |
| Standard | EN_12533 |
| Weight | 34.031 kg |
| Hardness of tread | Shore A 92 |
| Load capacity | 3200 kg |
| Load capacity (static) | 6400 kg |

Dimensions

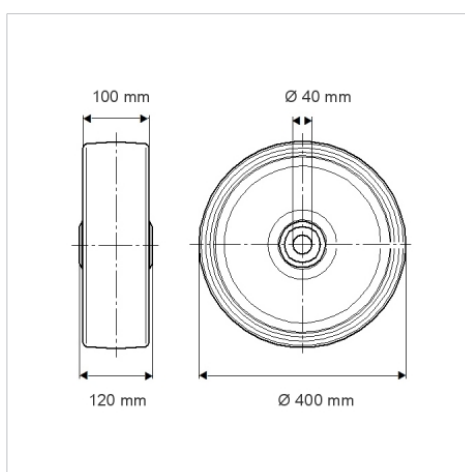

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ○ ○ |
| Movement noise | ● ● ● ○ ○ |
| Attrition | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ○ ○ |

Structure & Mounting

