

# MONO

## 5020PJI050L51-10 chrome

EAN 4031582364576

Swivel castor, housing made of Polyamide, with blind hole fitting. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Technical Data

Wheel diameter	50 mm
Wheel width	18 mm
Centre hole	10 mm
Offset	25 mm
Swivel Interference	104.4 mm
Overall height	72 mm
Temperature	- 20 / + 60 °C
Standard	EN_12528
Weight	0.54 kg
Swivel Radius	52.2 mm
Hardness of tread	Shore A 85
Load capacity	30 kg
Load capacity (static)	60 kg

### Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ○

### Dimensions

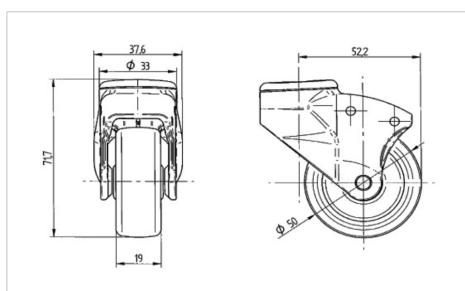

### Structure & Mounting

