

# MONO

A025PJI050L51-10 RAL7035

EAN 4031582359886

Swivel castor with wheel brake, housing made of Polypropylene, with blind hole fitting. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


## Technical Data

Wheel diameter	50 mm
Wheel width	18 mm
Centre hole	10 mm
Offset	25 mm
Swivel Interference	143.6 mm
Overall height	72 mm
Temperature	- 20 / + 60 °C
Standard	EN_12528
Weight	0.78 kg
Swivel Radius	71.8 mm
Hardness of tread	Shore A 85
Load capacity	30 kg
Load capacity (static)	60 kg

## Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ○

## Dimensions

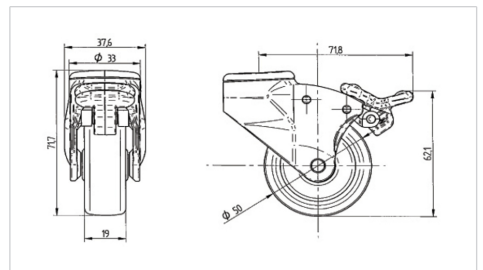

## Structure & Mounting

