

# LINEA

5947UAP100P30-11 RAL9002

EAN 4031582368673

Swivel castor with total lock, tail end of castor, housing made of Polyamide, precision ball bearing in swivel head, bolt hole. Wheel centre made of Polyamide, Tread: Polyurethane, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

|                        |                |
|------------------------|----------------|
| Wheel diameter         | 100 mm         |
| Wheel width            | 20 mm          |
| Castor width           | 82 mm          |
| Centre hole            | 11 mm          |
| Dome-Ø                 | 52 mm          |
| Offset                 | 32 mm          |
| Swivel Interference    | 216 mm         |
| Overall height         | 118 mm         |
| Temperature            | - 10 / + 40 °C |
| Standard               | EN_12530       |
| Weight                 | 0.706 kg       |
| Swivel Radius          | 108 mm         |
| Hardness of tread      | Shore A 92     |
| Load capacity          | 120 kg         |
| Load capacity (static) | 240 kg         |

## Structure & Mounting

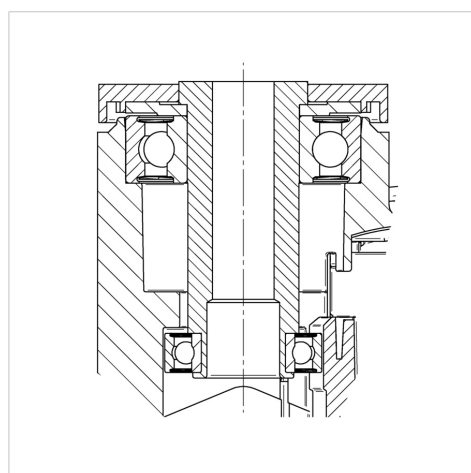

## Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ● ● |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ● ○ |