

# KAPPA

## 9652TOO160P63

EAN 4031582314892

Swivel castor with total lock, head end of castor, housing and plate steel-welded, bright zinc plated, blue passivated, sealed swivel bearing with dual purpose bearing and tapered roller bearing, threaded king pin and locking nut secured, grease nipple, wheel axle with nut, plate fitting. Wheel centre made of Polyamide, heavy duty, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Technical Data

|                        |                |
|------------------------|----------------|
| Wheel diameter         | 160 mm         |
| Wheel width            | 50 mm          |
| Size of Plate          | 135 x 110 mm   |
| Plate hole centres     | 105 x 80/75 mm |
| Plate hole             | 11 mm          |
| Offset                 | 58 mm          |
| Swivel Interference    | 276 mm         |
| Overall height         | 205 mm         |
| Temperature            | - 40 / + 80 °C |
| Standard               | EN_12533       |
| Weight                 | 4.399 kg       |
| Hardness of tread      | Shore D 75     |
| Load capacity          | 850 kg         |
| Load capacity (static) | 1700 kg        |


### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ● ● |
| Movement noise       | ● ○ ○ ○ ○ |
| Attrition            | ● ● ● ● ● |
| Corrosion resistance | ● ● ● ○ ○ |

### Dimensions

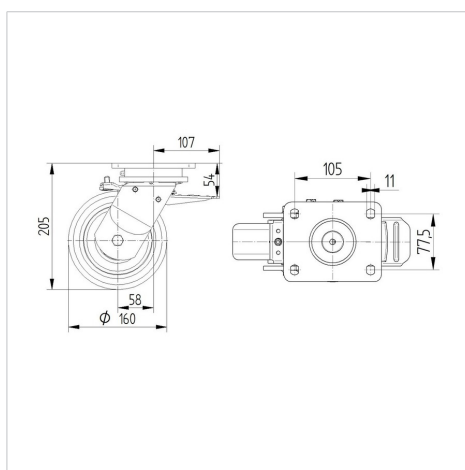

### Structure & Mounting

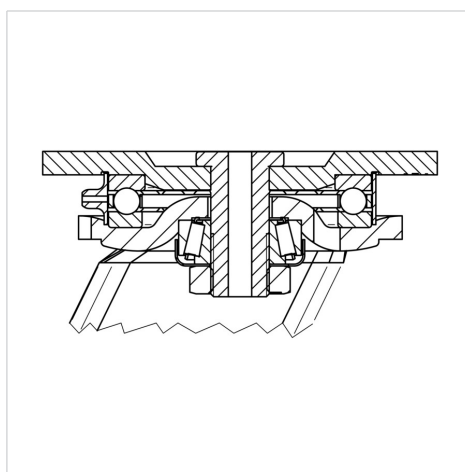

# KAPPA

9652TOO160P63

EAN 4031582314892



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

---

