

# STORA

2370PHP125P30-11

EAN 4031582364972

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, precision ball bearing, conditional antistatic according TENTE specifications



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

|                        |                |
|------------------------|----------------|
| Wheel diameter         | 125 mm         |
| Wheel width            | 32 mm          |
| Centre hole            | 11 mm          |
| Offset                 | 38 mm          |
| Swivel Interference    | 201 mm         |
| Overall height         | 155 mm         |
| Temperature            | - 20 / + 60 °C |
| Weight                 | 0.672 kg       |
| Swivel Radius          | 100.5 mm       |
| Hardness of tread      | Shore A 87     |
| Load capacity          | 100 kg         |
| Load capacity (static) | 200 kg         |

## Structure & Mounting

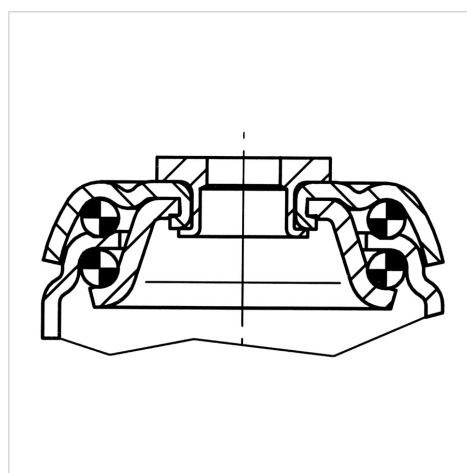

## Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ○ ○ |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ○ ○ |
| Corrosion resistance | ● ● ● ○ ○ |