

ALPHA

3470UAP200P63 BURDEOS

EAN 4031582440041

Swivel caster, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, dustguard, plate fitting. Wheel center made of Polyamide, Tread: Polyurethane, precision ball bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

Wheel diameter	7.87 in
Wheel width	1.97 in
Plate size	5.39 x 4.13 in
Plate hole centers	4.13 x 3.15/2.95 in
Plate hole	0.43 in
Offset	2.17 in
Swivel Interference	12.20 in
Overall height	9.45 in
Temperature	- 13 / + 140 °F
Standard	EN 12532
Weight	5.461 lbs
Swivel Radius	6.10 in
Hardness of tread	Shore D 60
Load capacity (dynamic)	770 lbs
Load capacity (static)	1545 lbs


Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ○ ○

Dimensions

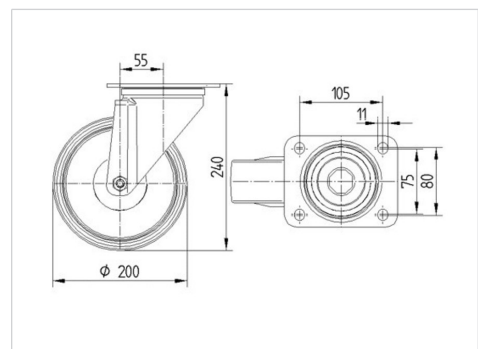

Structure & Mounting

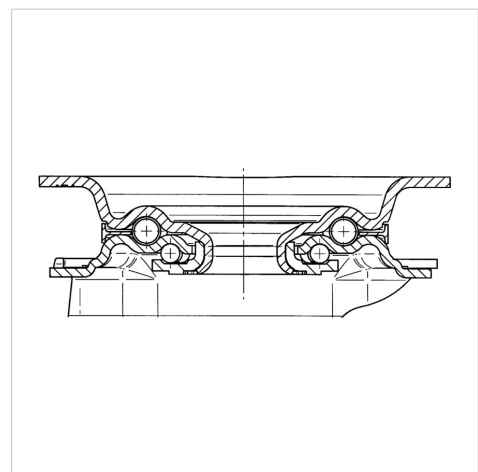

ALPHA

3470UAP200P63 BURDEOS

EAN 4031582440041



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

