

INTEGRAL

2046XSX200R26-28D45 D RAL9002 4xM8

EAN 4031582444834

Swivel caster with central lock, Frame made of pressed steel, precision ball bearing in swivel head and wheel, housing cover made of synthetic plastic, stem with cam hole for profile bars. Wheel center made of Polyamide, electric conductive, Tread made of injected Polyurethane, with threadguards, precision ball bearing, sealed.

Hint: TÜV Süd certified product. Washable casters must be sealed in the fitting area by the hospital bed manufacturer.



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	7.87 in
Wheel width	1.38 in
Bolt-Ø	1.10 in
Bolt length	3.78 in
Offset	2.36 in
Swivel Interference	12.60 in
Overall height	9.02 in
Temperature	- 22 / + 176 °F
Standard	EN 12531 (load capacity)
Weight	3.704 lbs
Swivel Radius	6.30 in
Hardness of tread	Shore D 59
Load capacity (dynamic)	330 lbs
Load capacity (static)	990 lbs

Dimensions

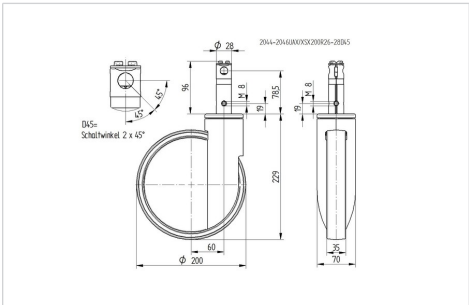

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○

INTEGRAL

2046XSX200R26-28D45 D RAL9002 4xM8

EAN 4031582444834



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

