

# LINEA

## 5920UAP050L51-10 LOAD RAL9002

EAN 4031582462470

Swivel caster, housing made of Polyamide, with blind hole fitting. Wheel center made of Polyamide, Tread: Polyurethane, precision ball bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Technical Data

|                         |                 |
|-------------------------|-----------------|
| Wheel diameter          | 1.97 in         |
| Wheel width             | 0.51 in         |
| Caster width            | 1.87 in         |
| Center hole             | 0.39 in         |
| Dome-Ø                  | 0.91 in         |
| Swivel Interference     | 3.19 in         |
| Overall height          | 1.97 in         |
| Temperature             | - 14 / + 104 °F |
| Standard                | EN 12530        |
| Weight                  | 0.183 lbs       |
| Swivel Radius           | 1.59 in         |
| Hardness of tread       | Shore A 92      |
| Load capacity (dynamic) | 220 lbs         |
| Load capacity (static)  | 440 lbs         |

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ● ● |
| Movement noise       | ● ● ● ● ○ |
| Attrition            | ● ● ● ● ● |
| Corrosion resistance | ● ● ● ● ○ |

### Dimensions

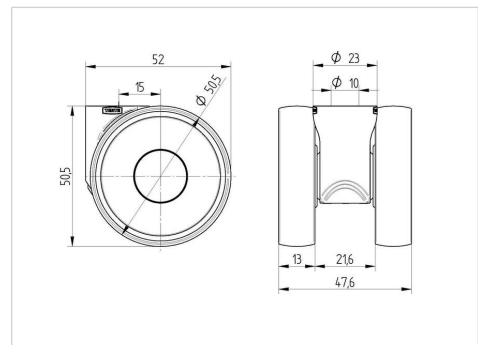

### Structure & Mounting

