

STYLEA

5920UOI065B10-11x20 DOM27

EAN 4031582335682

Swivel caster, housing made of Polyamide, stem with circlip. Wheel center made of Polyamide, plain bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	2.56 in
Wheel width	0.31 in
Caster width	1.69 in
Metal stem with circlip	0.43 x 0.79 in
Dome-Ø	1.06 in
Offset	0.98 in
Swivel Interference	4.17 in
Overall height	2.68 in
Temperature	- 4 / + 140 °F
Standard	EN 12528
Weight	0.273 lbs
Swivel Radius	2.09 in
Hardness of tread	Shore D 65
Load capacity (dynamic)	110 lbs
Load capacity (static)	220 lbs

Structure & Mounting

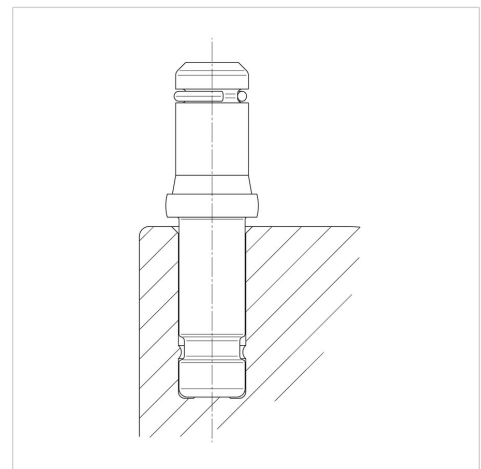

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ● ○