

# LEVINA

5370UAP150P30-13

EAN 4031582363418

Swivel caster, housing and wheels made from high grade synthetic materials, double ball bearing swivel head, bolt hole. Wheel center made of Polyamide, Tread: Polyurethane, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

Wheel diameter	5.91 in
Wheel width	1.26 in
Center hole	0.51 in
Offset	1.50 in
Swivel Interference	8.90 in
Overall height	7.48 in
Temperature	- 14 / + 104 °F
Standard	EN 12530
Swivel Radius	4.45 in
Hardness of tread	Shore D 40
Load capacity (dynamic)	220 lbs
Load capacity (static)	440 lbs

## Structure & Mounting

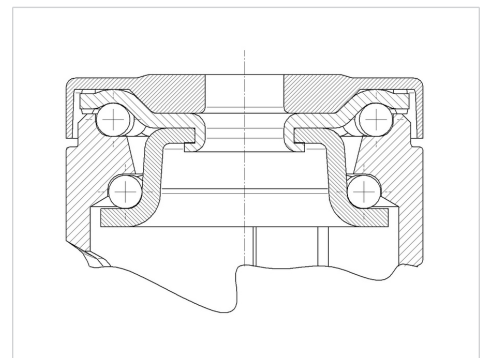

## Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ● ○

PRODUCT INFORMATION

# LEVINA

5370UAP150P30-13

EAN 4031582363418



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

---

