

LEVINA

5370UAP150P30-13

EAN 4031582363418

Swivel caster, housing and wheels made from high grade synthetic materials, double ball bearing swivel head, bolt hole. Wheel center made of Polyamide, Tread: Polyurethane, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

| | |
|-------------------------|-----------------|
| Wheel diameter | 5.91 in |
| Wheel width | 1.26 in |
| Center hole | 0.51 in |
| Offset | 1.50 in |
| Swivel Interference | 8.90 in |
| Overall height | 7.48 in |
| Temperature | - 14 / + 104 °F |
| Standard | EN 12530 |
| Swivel Radius | 4.45 in |
| Hardness of tread | Shore D 40 |
| Load capacity (dynamic) | 220 lbs |
| Load capacity (static) | 440 lbs |

Structure & Mounting

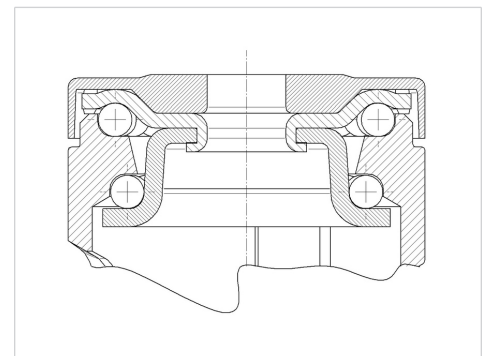

Advantages at a glance

| | |
|----------------------|-----------|
| Roll performance | ● ● ● ● ○ |
| Movement noise | ● ● ● ● ○ |
| Attrition | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ● ○ |

LEVINA

5370UAP150P30-13

EAN 4031582363418



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

