

# ALPHA

3478UAR080P62 red TBL

EAN 4031582272987

Fixed caster, Fork made of pressed steel, bright zinc plated, blue passivated, wheel axle with nut, plate fitting.  
Wheel center made of Polyamide, Tread: Polyurethane, roller bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

Wheel diameter	3.15 in
Wheel width	1.18 in
Plate size	4.06 x 3.35 in
Plate hole centers	3.15/3.03 x 2.36 in
Plate hole	0.35 in
Overall height	4.25 in
Temperature	- 13 / + 176 °F
Standard	EN 12532
Weight	0.992 lbs
Hardness of tread	Shore D 60
Load capacity (dynamic)	330 lbs
Load capacity (static)	660 lbs

## Dimensions

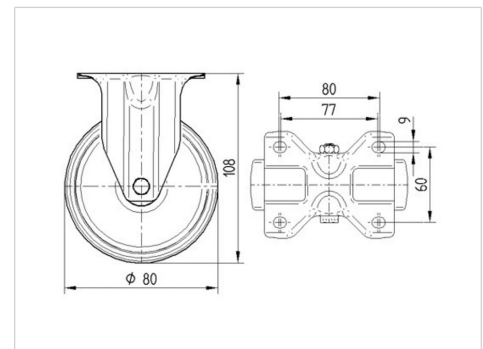

## Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ○ ○

# ALPHA

3478UAR080P62 red TBL

EAN 4031582272987



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

