

NOVATECH

ITP200x50-Ø20 flat

EAN 4031582070330

Wheel center made of Aluminum, Tread: Polyurethane, casted, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	7.87 in
Wheel width	1.97 in
Axle Hole-Ø	0.79 in
Hub length	2.36 in
Temperature	+ 14 / + 140 °F
Standard	EN 12532
Weight	2.844 lbs
Hardness of tread	Shore A 92
Load capacity (dynamic)	1765 lbs
Load capacity (static)	3525 lbs

Dimensions

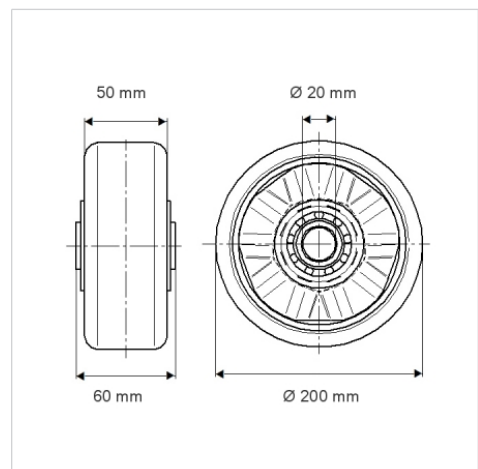

Advantages at a glance

Roll performance	● ● ● ● ●
Movement noise	● ● ● ● ●
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ● ●

Structure & Mounting

