

# LEVINA

5387PJC150R05-22 K

EAN 4031582426083

Swivel caster with total lock, trailing end of caster, housing made from high grade synthetic materials with metal parts made of Stainless Steel, double ball bearing swivel head, solid plug fitting. Wheel center made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, with threadguards, precision ball bearing, stainless  
Hint: These casters are available with grey locking lever.



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Technical Data

Wheel diameter	5.91 in
Wheel width	1.26 in
Bolt-Ø	0.87 in
Bolt length	1.77 in
Offset	1.50 in
Swivel Interference	9.45 in
Overall height	7.48 in
Temperature	- 14 / + 104 °F
Standard	EN 12530
Hardness of tread	Shore A 87
Load capacity (dynamic)	220 lbs
Load capacity (static)	440 lbs

## Structure & Mounting

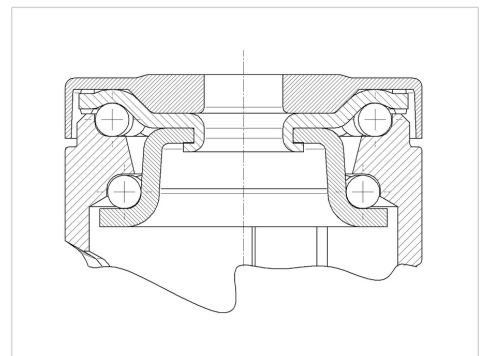

## Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ●

# LEVINA

5387PJC150R05-22 K

EAN 4031582426083



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

---

