

SCOUT

814WUAC160P60 180° TFR

EAN 4031582481778

Swivel castor, stainless steel housing with wheel brake and automatic directional stability, precision ball bearing in swivel bearing with long-life grease, swivel bearing with dust protection and grease nipple, wheel brake according to ball-pen principle, plate fitting Swivel castor with automatic directional stability and wheel brake, attacco a piastra. Wheel centre made of polyamide, tread made of polyurethane, two INOX precision ball bearings, sealed, washable

TENTE

BETTER MOBILITY. BETTER LIFE.




L'immagine potrebbe essere diversa dal prodotto originale

Informazioni Tecniche

Diametro ruota	160 mm
Larghezza della ruota	40 mm
Larghezza ruota	72 mm
Dimensione della piastra	130 x 74 mm
Interasse fori piastra	110 x 50 mm
Diametro fori piastra	10,5 mm
Disassamento	54 mm
Ingombro piroettamento	325 mm
Altezza utile	202 mm
Temperatura	-40 / +80 °C
Norma	EN_12532
Peso	2.8 kg
Raggio ingombro piroettamento	162.5 mm
Durezza della fascia	Shore A 92
Portata	250 kg
Portata statica	500 kg

Dimensioni

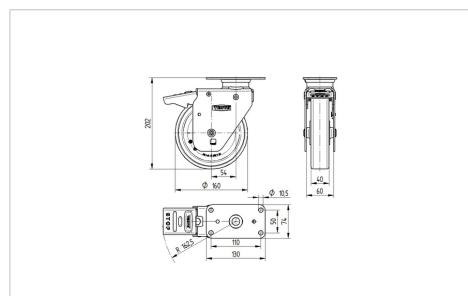

Caratteristiche

Resistenza al rotolamento	● ● ● ○ ○
Silenziosità	● ● ○ ○ ○
Abrasione	● ● ● ● ○
Protezione dalla corrosione	● ● ● ● ●